


CAT. N° 0 106 19

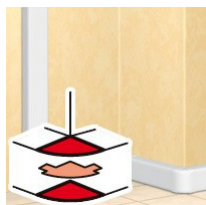

## EXTERNAL BEND 60-120° - FOR FLEXIBLE COVER DLP TRUNKING 50X105

Pack (number of units)	10
Volume (dm <sup>3</sup> )	9,106
Weight (g)	612,00

### Product characteristics

#### Angles for flexible cover universal trunking 50 x 105

##### Internal and external bends

- Include the 2 components for the top and bottom of the trunking on which the flexible cover is fitted
- Changeable external bend, from 60° to 120° for 50 x 105 mm trunkings

### General characteristics

#### Flexible cover universal DLP trunking 50 x 80 and 50 x 105 - 65 mm cover

- White

### Documentation



#### Catalogue pages & additional information

- [Selection chart \(p.820\)](#)
- [Description page \(p.822\)](#)
- [Flexible cover universal DLP trunking](#)



#### Agreements & certificates of conformity

- [NF 004 - 601796A](#)



#### Installation & technical data

- [F00885EN-03](#)
- [F00885FR-03](#)