


CAT. N° 0 208 06

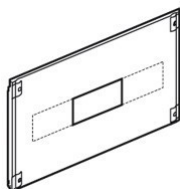

## METAL FACEPLATE XL<sup>3</sup> 800/4000 - FOR 2 DPX-IS 250 - 1/4 TURN - 24 MODULES

|                           |          |
|---------------------------|----------|
| Pack (number of units)    | 1        |
| Volume (dm <sup>3</sup> ) | 9        |
| Weight (g)                | 2 157,00 |

### Product characteristics

#### Metal faceplates

##### For 2 DPX-IS 250 in vertical position

- 24 modules
- For fastening and sealing
- 1/4 turn

### General characteristics

#### Equipment for XL<sup>3</sup> 4000 - for mounting on plate: DPX-IS 250, 630 and 1600

### Documentation

#### Catalogue pages & additional information

- [Selection chart \(p.262-263\)](#)
- [Description page \(p.269\)](#)
- [XL3 4000 equipment for mounting on adjustable plates](#)

#### Agreements & certificates of conformity

- [LOVAG - IT 12.067](#)
- [LOVAG - IT 12.075](#)
- [LOVAG - IT 12.017](#)
- [LOVAG - IT 12.074](#)
- [LOVAG - IT 12.019](#)
- [LOVAG - IT 12.073](#)