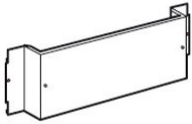


REF . 0 206 23

**PLATE XL<sup>3</sup> 800/4000 - FOR 1 DPX 630 FIXED - HORIZONTAL  
- 24 MODULES**

Emballage (nombre number of units )	1
Volume (dm <sup>3</sup> )	16
Poids (g)	2 841,00

**Caractéristiques du produit****Plates for fixed version DPX<sup>3</sup> 630/1600, with front terminals**

- Direct fixing on functional uprights

**Devices in horizontal position**

- For cut-out protection for cable passing, use seal Cat.No 0 202 40
- 24 modules
- For 1 DPX<sup>3</sup> 630 with or without earth leakage module

**Caractéristiques générales****Equipment for XL<sup>3</sup> 4000 - for mounting on fixed plate:  
DPX<sup>3</sup> 630 and DPX<sup>3</sup> 1600****Documentation associée****Catalogue pages & additional information**

- [Selection chart \(p.264-265\)](#)
- [Description page \(p.270\)](#)
- [XL3 4000 equipment for mounting on adjustable plates](#)

**Agreements & certificates of conformity**

- [LOVAG - IT 12.067](#)
- [LOVAG - IT 12.075](#)
- [LOVAG - IT 12.017](#)
- [LOVAG - IT 12.074](#)
- [LOVAG - IT 12.019](#)
- [LOVAG - IT 12.073](#)

**Installation instructions & related documents**

- [G5949B](#)