


CAT. N° 0 371 80

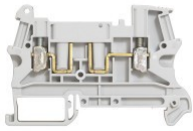

TERMINAL BLOCK VIKING 3 - SCREW - DISCONNECT - 1 CONNECT - OPEN - PITCH 6

Pack (number of units)	20
Volume (dm ³)	0,558
Weight (g)	258,00

Product characteristics

Disconnect terminal blocks 1 connection

- Opening by means of blade type lever, handle lever or mini lever (with tool)

Open (to be equipped)

- Can take blade type levers Cat.Nos 0 375 15/16/17/18 or in ELV installations a blade-type automotive fuse or a miniature circuit-breaker
- Colour : Grey
- Nominal cross-section : 2.5 mm²
- Capacity – Rigid wire : 0.25 to 2.5 mm²
- Capacity – Flexible wire with or without ferrules : 0.25 to 2.5 mm²
- Pitch : 6 mm

General characteristics

Viking™ 3 terminal blocks with screw connection - for copper cables

- Used to make the electrical connection between 2 flexible copper wires with or without ferrules or 2 rigid copper wires
- 2 areas for automatic insertion bridging combs up to 8 pitch (upper level only for multi-level blocks)
- For rails depth 15 mm, EN 60715 depth 7.5 mm and 15 mm

Documentation

Catalogue pages & additional information

- [Selection chart \(p.324-325\)](#)
- [Description page \(p.329\)](#)
- [Technical page \(p.335\)](#)
- [Viking™ 3 terminal blocks with screw connection](#)

Agreements & certificates of conformity

- [IMQ - CA02.04202](#)
- [NF App Industri - NF208_1011](#)
- [UL recogn - 20101029-E60900](#)
- [VERITAS \(BV\) - 23393/BO BV](#)

Installation & technical data

- [F01094EN-01](#)