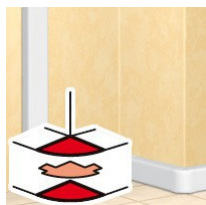


CAT. N° 0 106 19

**EXTERNAL BEND 60-120° - FOR FLEXIBLE COVER DLP TRUNKING 50X105**

Pack (number of units)	10
Volume (dm ³)	9,106
Weight (g)	612,00

Product characteristics**Angles for flexible cover universal trunking 50 x 105****Internal and external bends**

- Include the 2 components for the top and bottom of the trunking on which the flexible cover is fitted
- Changeable external bend, from 60° to 120° for 50 x 105 mm trunkings

General characteristics**Flexible cover universal DLP trunking 50 x 80 and 50 x 105 - 65 mm cover**

- White

Documentation **Catalogue pages & additional information**

- [Selection chart \(p.820\)](#)
- [Description page \(p.822\)](#)
- [Flexible cover universal DLP trunking](#)

 **Agreements & certificates of conformity**

- [NF 004 - 601796A](#)

 **Installation & technical data**

- [F00885EN-03](#)
- [F00885FR-03](#)