


CAT. N° 0 106 02

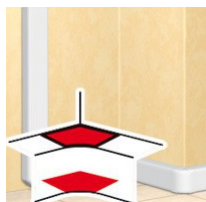

INTERNAL BEND 85-95° - FOR FLEXIBLE COVER DLP TRUNKING 50X80, ADAPTABLE DLP HEIGHT 50 (1 COMPARTMENT)

Pack (number of units)	10
Volume (dm ³)	11,036
Weight (g)	822,00

Product characteristics

Angles for flexible cover universal trunking 50 x 105

Internal and external bends

- Include the 2 components for the top and bottom of the trunking on which the flexible cover is fitted
- Changeable internal bend, from 85° to 95° for 50 x 80 / 50 x 105 / 50 x 150 and 50 x 195 mm trunkings

General characteristics

Flexible cover universal DLP trunking 35 x 105 and 50 x 105 - 85 mm cover

- White

Documentation

Catalogue pages & additional information

- [Selection chart \(p.820\)](#)
- [Selection chart \(p.821\)](#)
- [Description page \(p.822\)](#)
- [Description page \(p.824\)](#)
- [Flexible cover universal DLP trunking](#)

Agreements & certificates of conformity

- [NF 004 - 601796A](#)

Installation & technical data

- [F00885EN-02](#)