


CAT. N° 0 371 92

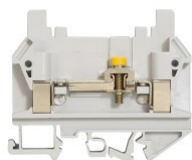

## TERMINAL BLOCK VIKING 3 - SCREW - DISCONNECT - 1 CONNECT - FOR MEASUREMENT

Pack (number of units)	25
Volume (dm <sup>3</sup> )	1,233
Weight (g)	631,00

### Product characteristics

#### Disconnect for measurement

##### 1 connection

- With its accessories, allows intervention (measurements, maintenance, etc) on a current, voltage and power measuring circuit by keeping the current transformer secondary circuit closed
- Colour : Grey
- Nominal cross-section : 4 mm<sup>2</sup>
- Capacity – Rigid wire : 0.25 to 4 mm<sup>2</sup>
- Capacity – Flexible wire with or without ferrules : 0.25 to 4 mm<sup>2</sup>
- Pitch : 8 mm

### General characteristics

#### Viking™ 3 terminal blocks with screw connection - for copper cables

- Used to make the electrical connection between 2 flexible copper wires with or without ferrules or 2 rigid copper wires
- 2 areas for automatic insertion bridging combs up to 8 pitch (upper level only for multi-level blocks)
- For rails depth 15 mm, EN 60715 depth 7.5 mm and 15 mm

### Documentation

#### Catalogue pages & additional information

- [Description page \(p.106\)](#)
- [Selection chart \(p.324-325\)](#)
- [Description page \(p.329\)](#)
- [Technical page \(p.335\)](#)
- [Current transformers \(CT\)](#)
- [Viking™ 3 terminal blocks with screw connection](#)