


CAT. N° 0 371 53

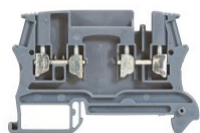

## TERMINAL BLOCK VIKING 3 - SCREW - FUNCTION BLOCK - 1 CONNECT - MODULAR - PITCH 5

Pack (number of units)	20
Volume (dm <sup>3</sup> )	0,558
Weight (g)	238,00

### Product characteristics

#### Function blocks

##### 1 connection - modular

- Component connected with screws
- Colour : Grey
- Nominal cross-section : 2.5 mm<sup>2</sup>
- Capacity – Rigid wire : 0.25 to 4 mm<sup>2</sup>
- Capacity – Flexible wire with or without ferrules : 0.25 to 2.5 mm<sup>2</sup>
- Pitch : 5 mm

### General characteristics

#### Viking™ 3 terminal blocks with screw connection - for copper cables

- Used to make the electrical connection between 2 flexible copper wires with or without ferrules or 2 rigid copper wires
- 2 areas for automatic insertion bridging combs up to 8 pitch (upper level only for multi-level blocks)
- For rails depth 15 mm, EN 60715 depth 7.5 mm and 15 mm

### Documentation



#### Catalogue pages & additional information

- [Selection chart \(p.324-325\)](#)
- [Description page \(p.329\)](#)
- [Technical page \(p.335\)](#)
- [Viking™ 3 terminal blocks with screw connection](#)