


CAT. N° 0 372 56

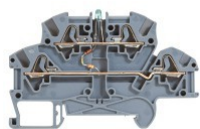

## TERMINAL BLOCK VIKING 3 - SPRING - FUNCTION BLOCK - 2 CONNECT - WITH LED

Pack (number of units)	60
Volume (dm <sup>3</sup> )	1,93
Weight (g)	868,00

### Product characteristics

#### Function blocks

##### 2 connections - 4 wires - 2 levels - with LED

- Voltage presence indicator (12/24V= and -)
- Colour : Grey
- Nominal cross-section : 4 mm<sup>2</sup>
- Capacity - Rigid wire : 0.5 to 6 mm<sup>2</sup>
- Capacity – Flexible wire : 0.5 to 4 mm<sup>2</sup>
- Flexible wire with ferrule : 0.5 to 2.5 mm<sup>2</sup>
- Pitch : 5 mm

### General characteristics

#### Viking™ 3 terminal blocks with spring connection - for copper cables

- Screwless connection system, stainless steel spring type
- Used to make the electrical connection between 2 rigid copper wires, or flexible copper wires with or without ferrules
- Direct tool-free insertion of a rigid wire or flexible wire with ferrule, up to 6 mm pitch
- 2 areas for automatic insertion bridging combs (upper level only for 2-level blocks)
- For rails depth 15 mm, EN 60715 depth 7.5 mm and 15 mm

### Documentation

#### Catalogue pages & additional information

- [Selection chart \(p.326-327\)](#)
- [Description page \(p.331\)](#)
- [Technical page \(p.336\)](#)
- [Viking™ 3 terminal blocks with spring connection](#)

#### Agreements & certificates of conformity

- [UL recogn - 20100921-E60900](#)
- [IMO - CA02.04199](#)
- [NF App Industri - NF208\\_1012](#)
- [VERITAS \(BV\) - 23393/BO BV](#)