


# Product sheet

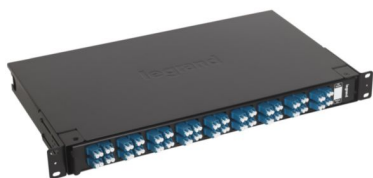

LCS<sup>3</sup> LEGRAND

Optic drawer 19 inches 1U rotating equipped with 36 LC duplex single-mode connectors for 72 fibres

REF. 032173 | EAN. 3414970958464

Metal 19 inches pre-equipped fibre optic drawers with 4 cable entries, supplied with screw fixing kit, 2 cable glands (diameter 13.5 and 16mm), coiling system and splicing cassette.

> [Visit e-catalogue](#)

## Description

Metal 19 inches pre-equipped fibre optic drawers with 4 cable entries, supplied with screw fixing kit, 2 cable glands (diameter 13.5 and 16mm), coiling system and splicing cassette.

### Product characteristics

- Maximum capacity : 36 LC singlemode connectors for 72 fibres
- Rotating : supplied with Left - to - Right opening, reversible.
- Panel and optic port marking on dedicated marking areas
- Height 1U, depth 220mm
- Black color

### Recommendation / Restriction

- Up to 72 fibers. Suitable for a large number of active devices. Recommended in the generic standards ISO/IEC 11801 and EN 50173.

## Documentation

### TECHNICAL DOCUMENTATION

-  S000095448FR-00.pdf | PDF (1.48Mo)
-  S000095448EN-00.pdf | PDF (1.08Mo)
-  LE09649AB.pdf | PDF (3.4Mo)

## The product's benefits

### Installation

- Supplied with screws and wiring accessories : 4 screws and nuts/4 screws, 2 cable glands (1 x PG16/1 x PG13.5), 2 accessories for coiling the fibres, 1 drawer holder for fixing on the rack, 1 splice holder, fitted but repositionable

### Usage

- Panel and optical ports marked on dedicated marking area.

### Avantages

- Panel marking area for labelling

### CATALOGUE PAGE & OTHERS

-  ex223001\_1000.pdf | PDF (0.13Mo)