


# Product sheet

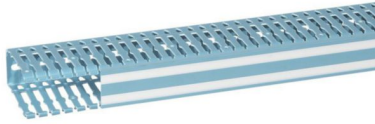

## LINA 25 LEGRAND

Cable ducting Lina 25 - w. 40 x h. 80 mm - blue 2525 - L. 2m

REF. 036208 | EAN. 3245060362089

> [Visit e-catalogue](#)

## Product characteristics

- Lina 25 ducting can be cut to length without using a saw. After making 2 lateral cuts with the Lina 25 tool, the ducting can be separated manually by a simple snap, thanks to the cut - outs on the bottom.
- Lina 25 ducting can be used to create a T junction between vertical and horizontal ducting without obstacles.
- Non-metal product, no electrical continuity.
- Blue 2525 AFNOR

## Recommendation / Restriction

- Recommended for industrial environments without any particular constraints.

## The product's benefits

### Installation

- Installation position : on vertical or horizontal surface, cover facing down not permitted.

### Usage

- The cover is easily fitted on the ducting either by clipping on the front or by rotating it. It can be opened without special tools.


## Documentation

### TECHNICAL DOCUMENTATION

 F01892EN-00.pdf | PDF (2.61Mo)

 F01892FR-00.pdf | PDF (2.6Mo)

### Agreements & Certificates

 UL recogn-E212478 | (0.09Mo)


 LGRP-01659-V01.01-EN.pdf | PDF (0.56Mo)

 NF Conduits-641237C | (0.18Mo)

### CATALOGUE PAGE & OTHERS

 ex223001\_0481.pdf | PDF (0.18Mo)

 ex223001\_0480.pdf | PDF (0.19Mo)

 ex223001\_0395.pdf | PDF (0.2Mo)