


Product sheet

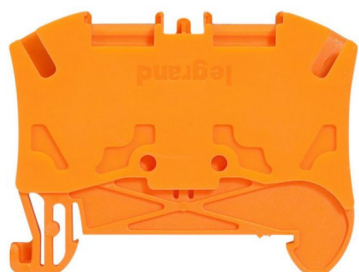

VIKING 3 LEGRAND

Connecting terminal block, spring connection, 1 connection 1entry/1outlet Cross-section 2,5mm² - pitch 5mm - orange

REF. 037220 | EAN. 3245060372200

> [Visit e-catalogue](#)

Product characteristics

- Orange terminal blocks are recommended for circuits not broken by the master isolating device.
- Direct tool - free insertion of a rigid wire or a flexible wire with ferrules, up to 6mm pitch
- 2 areas for automatic insertion bridging combs (upper level only for multi-level terminal blocks)
- Easy insertion of conductors thanks to the ergonomic shape of the entry and outlet.

Recommendation / Restriction

- Installation recommended for electrical connection in industrial and tertiary cabinets and enclosures.

The product's benefits

Installation

- A securing pin on the insulating body holds the Viking 3 terminal blocks together for ease of handling and perfect alignment on the rail. The assembly/disassembly of a terminal block is still possible without removing the adjacent terminal blocks

Usage

- Terminal blocks have two marking zones per level allowing a clear, visible and convenient identification of the circuit. Compatible with CAB 3 marking systems.

Documentation

TECHNICAL DOCUMENTATION

 F01007EN-02.pdf | PDF (1.06Mo)

 F01007FR-02.pdf | PDF (1.09Mo)

CAD & Design specs / BIM

 037220.dwg | DWG (0.05Mo)

CATALOGUE PAGE & OTHERS

 ex223001_0467.pdf | PDF (0.06Mo)

 ex223001_0468.pdf | PDF (0.05Mo)

 ex223001_0460.pdf | PDF (0.17Mo)

Agreements & Certificates

 IMQ-CA02.04198 | (0.82Mo)

 UL recogn-20100921-E60900 | (0.15Mo)

 ATEX-LCIE 16 ATEX 3049U - 02 | (0.71Mo)

 VERITAS (BV)-23393/C0 BV | (0.61Mo)

-  NF App Domestic-NF208_1012 | (1.06Mo)
-  Ex-002/j | (0.22Mo)