


Product sheet

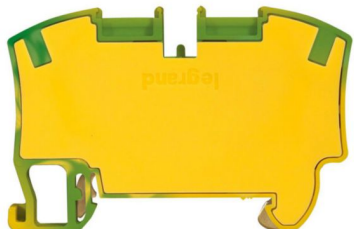

VIKING 3 LEGRAND

Connecting terminal block, screw connection, 1 connection 1entry/1outlets , Cross-section 4mm² -pitch 12mm -yellow/green

REF. 037274 | EAN. 3245060372743

> [Visit e-catalogue](#)

Product characteristics

- Green/yellow terminal blocks are recommended for protection conductors.
- Direct tool - free insertion of a rigid wire or a flexible wire with ferrules, up to 6mm pitch
- 2 areas for automatic insertion bridging combs (upper level only for multi-level terminal blocks)
- Easy insertion of conductors thanks to the ergonomic shape of the entry and outlet.

Recommendation / Restriction

- Installation recommended for electrical connection in industrial and tertiary cabinets and enclosures.

The product's benefits

Installation

- A securing pin on the insulating body holds the Viking 3 terminal blocks together for ease of handling and perfect alignment on the rail. The assembly/disassembly of a terminal block is still possible without removing the adjacent terminal blocks

Usage

- Terminal blocks have two marking zones per level allowing a clear, visible and convenient identification of the circuit.

Documentation

TECHNICAL DOCUMENTATION

-  F01007EN-02.pdf | PDF (1.06Mo)
-  F01007FR-02.pdf | PDF (1.09Mo)

CAD & Design specs / BIM

-  037274.dwg | DWG (0.1Mo)

CATALOGUE PAGE & OTHERS

-  ex223001_0467.pdf | PDF (0.06Mo)
-  ex223001_0468.pdf | PDF (0.05Mo)
-  ex223001_0460.pdf | PDF (0.17Mo)

Agreements & Certificates

-  UL recogn-20100921-E60900 | (0.15Mo)
-  Ex-002/i | (0.25Mo)
-  IMQ-CA02.04200 | (0.71Mo)
-  ATEX-LCIE 16 ATEX 3049U - 02 | (0.71Mo)
-  VERITAS (BV)-23393/C0 BV | (0.61Mo)



NF App Domestic-NF208_1009 | (0.28Mo)