


Product sheet

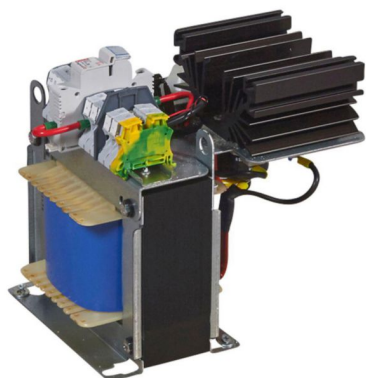

LEGRAND

Filtered single-phase rectified power supply - prim
230/400 V - 24 V= - 600 W - 25 A

REF. 047026 | EAN. 3245060470265

[> Visit e-catalogue](#)

Product characteristics

- Filtered rectified power supplies - High reliability power supplies without any pollution on electrical networks - Supplied with an insulated coupling bar for fast connection between the and T terminals up to 15 A - Clip - on only up to 24 W, clip - on or screw Fixing up to 120 W - Above 120 W : screw Fixing - Conform to standards IEC and EN 61558 - 2 - 6, UL 60950 and CAN/CSA - C22.2 No 60 950,00 - UL USA and Canada agreements up to 240 W - Products suitable for building equipment conforming to standards EN 61131 - 2, EN 60204 and EN 60439 - 1
- Single-phase power supplies - Consisting of : - a safety transformer with interference filtering - Double operating terminals - filter capacitors - fused protection In =he secondary - a green operating voltage present indicator24 V - 230 - 400 V $\pm$ 15 V~ (primary) / 24 V (secondary) - Output : 600 W - Current : 25 A - Terminal capacity Flexible cables Input : 6 - Terminal capacity Flexible cables Output : 10

Documentation

CATALOGUE PAGE & OTHERS

 [ex223001_0511.pdf](#) | PDF (0.07Mo)

CAD & Design specs / BIM

 [047046.dwg](#) | DWG (0.08Mo)