


# Product sheet

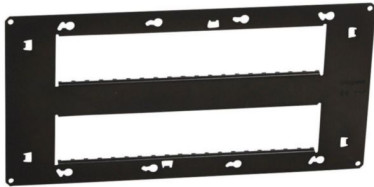

MOSAIC™ LEGRAND

Mosaic™ - Support - for 2 x 10 modules

REF. 080268 | EAN. 3245060802684

> [Visit e-catalogue](#)

## Product characteristics

- supports with site protection - For 2 x 10 modules - Without site protection

## Documentation

### TECHNICAL DOCUMENTATION

 F00440FR-02.pdf | PDF (0.66Mo)

 F00440EN-02.pdf | PDF (0.66Mo)

### CAD & Design specs / BIM

BIM-LEGRAND-MOSAIC-2025-FRANCAIS.rvt | RVT (124.38Mo)

BIM-LEGRAND-MOSAIC-2025-ENGLISH.rvt | RVT (125.73Mo)

### CATALOGUE PAGE & OTHERS

 ex223001\_1204.pdf | PDF (0.18Mo)

### Agreements & Certificates

 NF App Domestic-NF012\_4571/M1 | (1Mo)

 B.B.J-B/12/006/24 | (3.34Mo)

 AENOR-030/002285 | (0.47Mo)

 OC / CB-FR\_707532/M1 | (1.51Mo)

 OC / CB-FR\_705591/A3 | (0.73Mo)

 OC / CB-FR\_707308/A3 | (4.23Mo)

 MEEI-UP 69267544 001 | (2.21Mo)

 OC / CB-HU-005377 | (0.56Mo)

 NF App Domestic-NF012\_2275/A2 | (0.96Mo)

 NF App Domestic-NF012\_4512/M1 | (0.91Mo)

 OC / CB-HU-005009-A1/M1 | (0.73Mo)

 B.B.J-B12/005/24 | (4.62Mo)

 OC / CB-HU-005022-M1 | (0.7Mo)

 NF App Domestic-NF012\_2201/A2 | (1.3Mo)

 MEEI-UP 69267544 002 | (1.23Mo)