


Product sheet

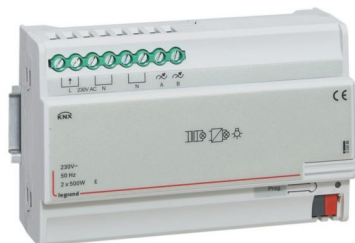

LEGRAND

KNX controller dimming universal rlc din 2 outputs

REF. 002686 | EAN. 3414970601506

> [Visit e-catalogue](#)

Product characteristics

- 2 outputs - 500 VA max each
- DIN 8 modules
- Power supply from KNX bus (= 12mA)

Recommendation / Restriction

- Configuration through ETS tool from KNX association

The product's benefits

Installation

- Connected with the BUS/KNX cable

Usage

- Integrated automatic learning phase for the associated loads (R, L or C type loads)

Advantages

- Configuration of normal/timer operating mode and behaviour on reception of switch on command and/or configurable dimming command
- Predefined configurable dimming values
- Up to 15 configurable scenes

Documentation

TECHNICAL DOCUMENTATION

- S000095126EN-1.pdf | PDF (1.35Mo)
- LE05504AB_EN.pdf | PDF (2.96Mo)
- LE05504AC_FR.pdf | PDF (6.12Mo)
- LE07510AC.pdf | PDF (0.33Mo)

Agreements & Certificates

- KNX EIB-11/11668/14 | (0.25Mo)

CATALOGUE PAGE & OTHERS

- ex223001_0896.pdf | PDF (0.07Mo)

Software & configurators

- FW-LG-002686.zip | ZIP (0.04Mo)
- FW_LG-002638_2.zip | ZIP (8.46Mo)