


# Product sheet

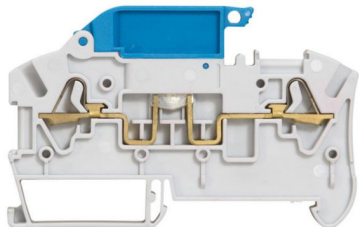

## VIKING 3 LEGRAND

Disconnect terminal block, spring connection, 1 connection 1 entry/1outlet, 2,5mm<sup>2</sup> - pitch 6 - grey for neutral circuit

REF. 037282 | EAN. 3245060372828

> [Visit e-catalogue](#)

## Product characteristics

- Grey terminal blocks are recommended for standard circuits. Blue terminal blocks are recommended for neutral conductor.
- Direct tool - free insertion of a rigid wire or a flexible wire with ferrules, up to 6mm pitch
- 2 areas for automatic insertion bridging combs (upper level only for multi-level terminal blocks)
- Easy insertion of conductors thanks to the ergonomic shape of the entry and outlet.

## Recommendation / Restriction

- Installation recommended for electrical connection in industrial and tertiary cabinets and enclosures.

## The product's benefits

### Installation


- A securing pin on the insulating body holds the Viking 3 terminal blocks together for ease of handling and perfect alignment on the rail. The assembly/disassembly of a terminal block is still possible without removing the adjacent terminal blocks

### Usage





- Terminal blocks have two marking zones per level allowing a clear, visible and convenient identification of the circuit.

## Documentation

### CATALOGUE PAGE & OTHERS

-  [ex223001\\_0467.pdf](#) | PDF (0.06Mo)
-  [ex223001\\_0468.pdf](#) | PDF (0.05Mo)
-  [ex223001\\_0461.pdf](#) | PDF (0.14Mo)

### Agreements & Certificates

-  [UL recogn-20100921-E60900](#) | (0.15Mo)
-  [VERITAS \(BV\)-23393/C0 BV](#) | (0.61Mo)
-  [IMQ-CA02.04199](#) | (0.88Mo)
-  [NF App Industri-NF208\\_1012](#) | (1.06Mo)