


Product sheet

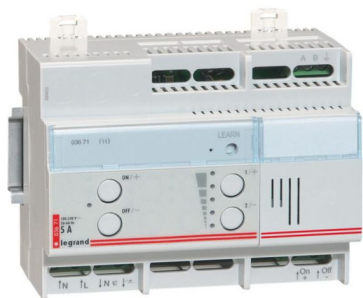

LEGRAND

Remote control dimmer via BUS line -
incandescent/halogen lamp - DIN 6 modules

REF. 003671 | EAN. 3245060036713

> [Visit e-catalogue](#)

Product characteristics

- For incandescent and halogen lamps 230VAC, ELV halogen lamps with ferromagnetic or electronic transformers
- Load : 1000W (for 230VAC 50/60Hz)
- Mains voltage 100/240VAC - 50/60Hz
- DIN 6 modules
- Equipped with illuminated scale indicating the light level of controlled lamps

The product's benefits

Installation

- Symmetrical rail mounting

Usage

- Equipped with illuminated scale indicating the light level of controlled lamps

Advantages

- Equipped with illuminated scale indicating the light level of controlled lamps

Documentation

TECHNICAL DOCUMENTATION

→ [0064JR3-03_EN.pdf](#) | PDF (0.62Mo)

→ [0064JR3-03_FR.pdf](#) | PDF (0.62Mo)

CAD & Design specs / BIM

 [003671.dwg](#) | DWG (0.12Mo)

CATALOGUE PAGE & OTHERS

 [ex223001_0108.pdf](#) | PDF (0.08Mo)