


Product sheet

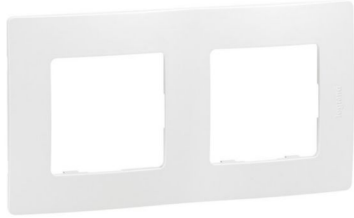

NILOÉ™ LEGRAND

Plate Niloé - 2 gang - white

REF. 665002 | EAN. 3245066650029

> [Visit e-catalogue](#)

Product characteristics

- Nilo - plates
- 2-gang - White

Documentation

TECHNICAL DOCUMENTATION

-  F01775EN-02.pdf | PDF (0.45Mo)
-  F01775FR-02.pdf | PDF (1Mo)
-  F01207EN-02.pdf | PDF (1.45Mo)
-  F01207FR-02.pdf | PDF (1.45Mo)

Agreements & Certificates

-  OC / CB-FR_717989 | (0.6Mo)
-  LGRP-00040-V01.01-FR.pdf | PDF (0.76Mo)
-  B.B.J-B/12/027/21 | (2.93Mo)
-  OC / CB-FR_705601 | (1.36Mo)
-  OC / CB-HU-002606 | (0.13Mo)
-  B.B.J-B/12/019/21 | (2.83Mo)
-  OC / CB-677867 | (0.76Mo)
-  OC / CB-FR_705448/A1 | (0.51Mo)
-  LGRP-00036-V02.01-FR.pdf | PDF (0.76Mo)
-  LGRP-00038-V01.01-FR.pdf | PDF (0.77Mo)
-  LGRP-00400-V02.01-EN.pdf | PDF (0.68Mo)
-  OC / CB-675833 | (1.8Mo)
-  OC / CB-610789B/M3 | (2.29Mo)

CATALOGUE PAGE & OTHERS

-  ex223001_0749.pdf | PDF (0.11Mo)

-  CEBEC-18687 | (2.47Mo)
-  OC / CB-677932 | (1.81Mo)
-  LGRP-00182-V01.01-FR.pdf | PDF (0.7Mo)
-  OC / CB-HU-002640 | (0.18Mo)
-  LGRP-00039-V01.01-FR.pdf | PDF (0.77Mo)
-  VDE-40034171 | (0.37Mo)
-  NF-677930 | (1.13Mo)
-  CEBEC-18685 | (2.1Mo)
-  LGRP-01578-V01.01-EN.pdf | PDF (0.7Mo)
-  NF-677924 | (1.38Mo)
-  CEBEC-18686 | (3.26Mo)
-  LGRP-00037-V01.01-EN.pdf | PDF (0.77Mo)
-  OC / CB-FR_675842/M1 | (0.81Mo)
-  OC / CB-686066B | (0.45Mo)