


Product sheet

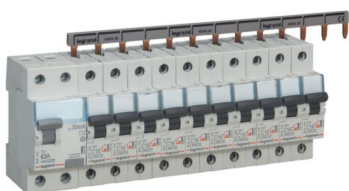

LEGRAND

RCCB TX³ - 2P 230 V~ - 30 mA - 63 A - AC type - do not accept auxiliaries

REF. 403002 | EAN. 3245064030021

> [Visit e-catalogue](#)

Product characteristics

- RCCBs TX³ - residual current circuit breakers - from 25 A to 63 A - AC and A types - Conform to IEC 61008 - 1 - Compatible with prong - type supply busbars - AC type : detect AC component faults - A type : detect AC and DC component faults - Do not accept auxiliaries
- 2-pole - 230 V~AC type - Sensitivity : 30 mA - In : 63 A - Number of modules : 2

Documentation

TECHNICAL DOCUMENTATION

 [F01540EN-02.pdf](#) | PDF (0.58Mo)

CAD & Design specs / BIM

 [403000.dwg](#) | DWG (0.15Mo)

CATALOGUE PAGE & OTHERS

 [ex223001_0055.pdf](#) | PDF (0.08Mo)

Agreements & Certificates

 [LGRP-02039-V01.01-EN.pdf](#) | PDF (0.76Mo)

 [LGRP-00366-V02.01-FR.pdf](#) | PDF (0.6Mo)

 [OC / CB-CB FR_713498/M1](#) | (2.3Mo)

 [VDE-40036431](#) | (0.39Mo)

 [LGRP-00366-V02.01-EN.pdf](#) | PDF (0.64Mo)