


Product sheet

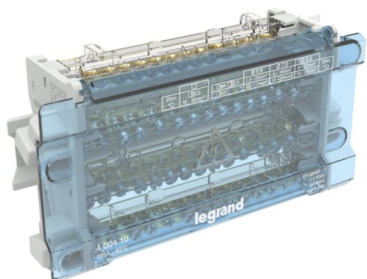

XL³ LEGRAND

Modular distribution block with staggered bars 125 A - external output - 16 connections/bar - 10 modules

REF. 400410 | EAN. 3414971978690

> [Visit e-catalogue](#)

Product characteristics

- Input Inputer 16 - 35 mm² solid or 16 - 35 mm² stranded with ferrule
- 15 Output : 2 x 10 - 35 + 1 x 10 - 25 + 12 x 2.5 - 10 mm² rigid conductor
- 15 output : 2 x 6 - 25 + 1 x 6 - 16 + 12 x 1.5 - 10 mm² flexible conductor with or without ferrule
- In = 125A - 40°C Ui = 500 V
- Ipk = 20 kA - 60 ms Icw = 4,5 kA - 1s

The product's benefits

Installation

- Easy and fast cabling and connecting thanks to a maximised cabling space , optimized "orientation" of bars and adapted dimensions and positions of connections

Usage

- Transparent , removable and 180° rotating cover to adapt to all wiring situations

Advantages

- Maximised internal space and optimised bar orientation for easy cable access
- Connections sized and positioned to facilitate connection and answer all needs
- integrated system, to avoid accidental unscrewing of non connected screws

Documentation

TECHNICAL DOCUMENTATION

 F03358EN-02.pdf | PDF (2.35Mo)

 F03358FR-02.pdf | PDF (1.79Mo)

CAD & Design specs / BIM

 400410.dwg | DWG (0.49Mo)

CATALOGUE PAGE & OTHERS

 ex223001_0299.pdf | PDF (0.13Mo)