


# Product sheet

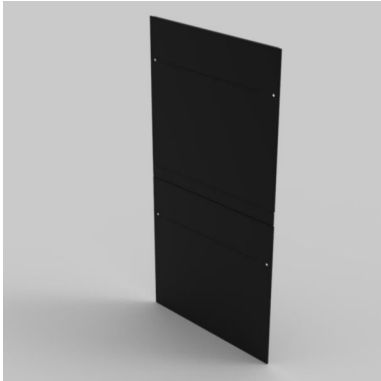

## NEXPAND LEGRAND

One divided side panel for left/right side of server cabinet 42U depth 1000mm with plinths

REF. 446420 | EAN. 3414972237413

One side panel divided in two parts for server cabinet including plinths. Used when standalone is preferred or when the cabinet is placed at the end of the row.

> [Visit e-catalogue](#)

## Description

One side panel divided in two parts for server cabinet including plinths. Used when standalone is preferred or when the cabinet is placed at the end of the row.

### Product characteristics



- For server cabinets, 42U depth 1000mm
- Horizontally divided panels for easy handling
- Aluminium
- Earthing connection is established when locking the panels
- Black RAL 9005 (same color as the cabinet)

### Recommendation / Restriction

- Set is intended for one side of the cabinet. Can be placed on the left or right side according to your needs.

## Documentation

### TECHNICAL DOCUMENTATION

- [HCNI-000002\\_LP\\_EN.pdf](#) | PDF (3.38Mo)
-  [LCS3\\_CABLING-TDV05-Print-Ready\\_EN.pdf](#) | PDF (12.21Mo)
-  [LCS3\\_SERVERCABINET-TDV05-Print-Ready\\_EN.pdf](#) | PDF (15.62Mo)

## The product's benefits

### Installation

- Horizontally divided panel for easy handling

### CATALOGUE PAGE & OTHERS

-  [ex223001\\_1010.pdf](#) | PDF (0.06Mo)