


CAT. N° 0 106 35

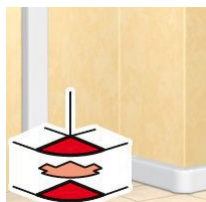

EXTERNAL ANGLE 60-120° - FOR FLEXIBLE COVER DLP TRUNKING + ADAPTABLE DLP 50X150/195 (2 COMPARTMENT)

Pack (number of units)	5
Volume (dm ³)	4,782
Weight (g)	344,00

Product characteristics

Angles for flexible cover universal trunking 50 x 105

Internal and external bends

- Include the 3 components making the angle (parts for the top and bottom and the partition junction) on which the flexible cover is fitted
- Changeable external bend, from 60° to 120° for 50 x 150 and 50 x 195 mm trunkings

General characteristics

Flexible cover universal DLP trunking 50 x 195 - 85 mm cover

- White

Documentation

Catalogue pages & additional information

- [Selection chart \(p.820\)](#)
- [Description page \(p.823\)](#)
- [Description page \(p.825\)](#)
- [Flexible cover universal DLP trunking](#)

Agreements & certificates of conformity

- NF 004 - 601796A

Installation & technical data

- [F00885EN-03](#)
- [F00885FR-03](#)