


CAT. N° 0 372 82

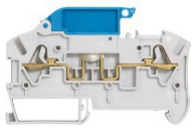

## TERMINAL BLOCK VIKING 3 - SPRING - DISCONNECT - FOR NEUTRAL CIRCUIT

|                           |        |
|---------------------------|--------|
| Pack (number of units)    | 20     |
| Volume (dm <sup>3</sup> ) | 0,626  |
| Weight (g)                | 275,00 |

### Product characteristics

#### Disconnect terminal blocks 1 connection - 2 wires

- Opening by means of blade type lever, handle lever or mini lever (with tool)

#### For neutral circuit with blue handle lever

- Colour : Grey/blue
- Nominal cross-section : 2.5 mm<sup>2</sup>
- Capacity - Rigid wire : 0.5 to 2.5 mm<sup>2</sup>
- Capacity – Flexible wire : 0.5 to 2.5 mm<sup>2</sup>
- Flexible wire with ferrule : 0.5 to 2.5 mm<sup>2</sup>
- Pitch : 6 mm

### General characteristics

#### Viking™ 3 terminal blocks with spring connection - for copper cables

- Screwless connection system, stainless steel spring type
- Used to make the electrical connection between 2 rigid copper wires, or flexible copper wires with or without ferrules
- Direct tool-free insertion of a rigid wire or flexible wire with ferrule, up to 6 mm pitch
- 2 areas for automatic insertion bridging combs (upper level only for 2-level blocks)
- For rails depth 15 mm, EN 60715 depth 7.5 mm and 15 mm

### Documentation



#### Catalogue pages & additional information

- [Selection chart \(p.326-327\)](#)
- [Description page \(p.331\)](#)
- [Technical page \(p.336\)](#)
- [Viking™ 3 terminal blocks with spring connection](#)



#### Agreements & certificates of conformity

- UL recogn - 20100921-E60900
- IMQ - CA02\_04199
- NF App Industri - NF208\_1012
- VERITAS (BV) - 23393/BO BV