


CAT. N° 0 390 20

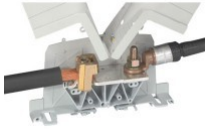

POWER TERMINAL BLOCK VIKING 3 - CABLE-CABLE LUG - PITCH 42

Pack (number of units)	5
Volume (dm ³)	7,84
Weight (g)	2 650,00

Product characteristics

Insulated aluminium/copper power terminal blocks

- For aluminium/copper cables, copper bars or cable lugs
- Direct connection of cable
- Insulation and protection against direct contact without additional accessories (built-in dividers and covers)
- Pre-cut removable covers for adjustment to the various connection modes
- Fixed using metal clip for rails 15 mm depth and EN 60715 15 mm depth, or on plate with screws
- Permits the use of Cab 3, Duplix markers
- Test via test plug closed covers
- Blocks with identical pitch can be joined using a threaded rod
- Shunting possible with Cat.Nos 0 394 46/47

Cable - cable lug

- Rigid or flexible cable : Al/Cu 35 to 120 mm²
- Rigid or flexible cable : Al/Cu 120 mm²
- Pitch : 42 mm

General characteristics

Viking™ 3 power terminal blocks

- Bridging the gap between the enclosure and external cables

Documentation



Catalogue pages & additional information

- [Description page \(p.338\)](#)
- [Technical page \(p.339\)](#)



Agreements & certificates of conformity

- [UL recogn-E60900 Vol 1 Sec7](#)