


REF . 3 387 75

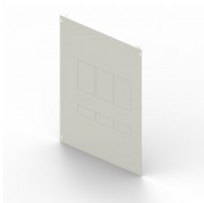

**FACEPLATE FOR XL<sup>3</sup> S 630 AND 4000 24-MODULE ENCLOSURE - FOR DPX<sup>3</sup> 630 4P WITH E.L.C.BS - VERTICAL MOUNTING**



Emballage (nombre number of units )	1
Volume (dm <sup>3</sup> )	12,875
Poids (g)	3 285,00

**Caractéristiques du produit**

**Faceplates for DPX<sup>3</sup> 630 - vertical mounting**

- Fixed with locking clips, 1/4 turn screws or screws

**With e.l.c.bs**

- 4P with e.l.c.bs
- For 24-module enclosure

**Caractéristiques générales**

**XL<sup>3</sup> S 4000 - equipment for mounting DPX<sup>3</sup> 630 and DRX 630 on a plate**

**Documentation associée**

 **Catalogue pages & additional information**

- [Selection chart \(p.232-233\)](#)
- [Description page \(p.239\)](#)
- [Selection chart \(p.244-245\)](#)
- [Description page \(p.250\)](#)

 **Agreements & certificates of conformity**

- [LOVAG-IT 17](#)
- [LOVAG-IT 18](#)
- [LOVAG-IT 18](#)
- [LOVAG-IT 18](#)
- [LOVAG-IT 18](#)
- [LOVAG-IT 18](#)
- [LOVAG-IT 18](#)
- [LOVAG-IT 18](#)

 **Installation & technical data**

- [F02370EN-02](#)

 **Environmental product profile**

- [LGRP-00470-V01](#)