


CAT. N° 4 461 80

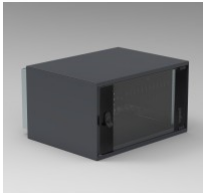

## WALL-MOUNTING ENCLOSURES LCS<sup>3</sup> WITH GLASS DOOR - CAPACITY 6U - WIDTH 600 MM , DEPTH 525 MM AND HEIGHT 342 MM

Pack (number of units)	1
Volume (dm <sup>3</sup> )	89,774
Weight (g)	19 000,00

### Product characteristics

#### Wall-mounting cabinets with glass door

- Comprise:
  - a wall element with integrated strain relief profile
  - 4 front and rear bars
  - 2 cable entry plates (top and bottom)
  - a set of two 19" profiles with adjustable depth (in steps of 50 mm) and a pattern of holes on the side allowing accessories to be fitted. The casing consists of two identical upper and lower panels with ventilation slots at the rear, two identical side panels and a Securit glass door with an EK-333 lock and a handle. Possibility to adjust the cable holes' size on the spot thanks to the handy bend-way fingers
- Width: 600 mm
- Colour: RAL 9011
- Finishing: powder coating
- Max. load: 100 kg
- Supplied with 1 rear plate, 4 depthwise bars, 2 cable entry plates, 2 x 19" profiles, 2 roof and floor plates, 2 side panels, 1 glass door, 1 assembly set, including assembly guide
- Capacity : 6 U
- Width : 600 mm
- Depth : 525 mm
- Height : 342 mm

### General characteristics

#### Legrand cabling system LCS<sup>3</sup> enclosures - wall-mounting cabinets

### Documentation

#### Catalogue pages & additional information

- [Description page \(p.766\)](#)

#### Installation & technical data

- [Datasheet LCS3 wall enclosure](#)

#### Installation instructions & related documents

- [005X0-344-0C](#)