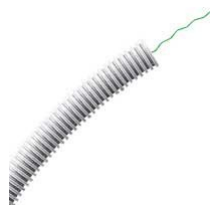


CAT. N° 6 510 50

**FLEXIBLE CONDUIT - MEDIUM IMPACT - SHOCK RESISTANCE 2 JOULES - Ø EXT. 50 MM**

|                           |           |
|---------------------------|-----------|
| Pack (number of metres)   | 50        |
| Volume (dm <sup>3</sup> ) | 254       |
| Weight (g)                | 10 700,00 |

**Product characteristics****Medium impact (ICA 3321)**

- Material: PVC without Pb, Sn, Cd (RoHS compliant)
- Light grey (RAL 7035)
- Impact resistance: 2 joules at - 5 °C
- Min operating t°: - 5 °C
- Max operating t°: + 60 °C
- IK 07
- Flush-mounted in certain cases before construction of the masonry
- Ø exterior: : 50 mm
- Ø interior: : 39.6 mm
- colour of ties on coil: : white

**General characteristics****Flexible conduits**

- Non flame propagating
- Conform to standard EN/IEC 61386-22
- Crush resistance: 750 Newtons
- Supplied wrapped in film, the coil acts as a pay-out reel
- The various diameters are identified by coloured ties
- Surface-mounting or flush-mounting

**Documentation****Catalogue pages & additional information**

- [Description page \(p.619\)](#)
- [Flexible conduits](#)

**Agreements & certificates of conformity**

- [NF 004 - 60050610C1](#)